




## Splice Wallet Instructions

### General

This instruction sheet provides procedures for installing the **Uniprise®** splice wallet, multiple splice organizer management system and is intended for indoor use or can be used outdoors in a suitable protective enclosure.

Ordering information is listed below:

Order No.	Product Code	Description
760148411	KIT-SW-48-SFS-2FD	3X splice wallet w/ 3 fusion splice trays and 2 fiber drums
760148437	KIT-SW-96-SFS-2FD	6X splice wallet w/ 6 fusion splice trays and 2 fiber drums
760154682	KIT-SW-96-SFS-2FD-1U	(2) 3X splice wallets w/ 6 fusion splice trays and 2 fiber drums
760148452	KIT-SW-96-SFS-4FD	6X splice wallet w/ 6 fusion splice trays and 4 fiber drums
760148478	KIT-SW-192-SFS-4FD	(2) 6X splice wallets w/ 12 fusion splice trays and 4 fiber drums
760148429	KIT-SW-36-MES-2FD	3X splice wallet w/ 3 mechanical (rotary) splice trays and 2 fiber drums
760148445	KIT-SW-72-MES-2FD	6X splice wallet w/ 6 mechanical (rotary) splice trays and 2 fiber drums
760148460	KIT-SW-72-MES-4FD	6X splice wallet w/ 6 mechanical (rotary) splice trays and 4 fiber drums
760148486	KIT-SW-144-MES-4FD	(2) 6X splice wallets w/ 12 mechanical (rotary) splice trays and 4 fiber drums

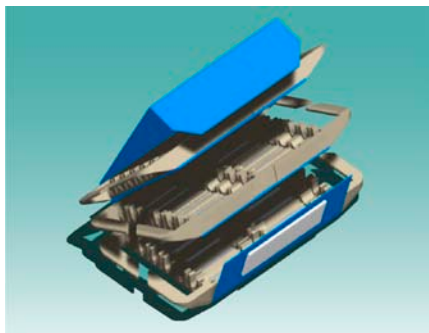

**3X Splice Wallet**



**6X Splice Wallet**

### How to Contact Us

- To find out more about **CommScope®** products, visit us on the web at <http://www.commscope.com/>
- For technical assistance:
  - Within the United States, contact your local account representative or technical support at 1-800-344-0223. Outside the United States, contact your local account representative or Authorized Business Partner.
  - Within the United States, report any missing/damaged parts or any other issues to **CommScope** Customer Claims at 1-866-539-2795. Outside the United States, contact your local account representative or Authorized Business Partner.

This product is covered by one or more of the following U.S. patents or their foreign equivalents: 7,113,687 B2.

## Materials Required


- Isopropyl alcohol
- Lint-free cloth or tissue

## Cautions

- Isopropyl alcohol is flammable, and can cause eye irritation on contact. If eye contact occurs, flush with water for at least 15 minutes. In case of ingestion, consult a physician. Use only in well ventilated areas.

## Step 1 – Verify Kit Number and Contents


Quantity									Description
760148411	760148437	760154682	760148452	760148478	760148429	760148445	760148460	760148486	
1		2			1				3X splice wallet
	1		1	2		1	1	2	6X splice wallet
					3	6	6	12	Mechanical (rotary) splice tray
3	6	6	6	12					Fusion splice tray
2	2	2	4	4	2	2	4	4	Fiber storage drum
2	2	2	2	2	2	2	2	2	8-32 x 1.5 screw
2	2	2	2	2	2	2	2	2	Retainer nut
1	1	1	1	1	1	1	1	1	Instruction sheet

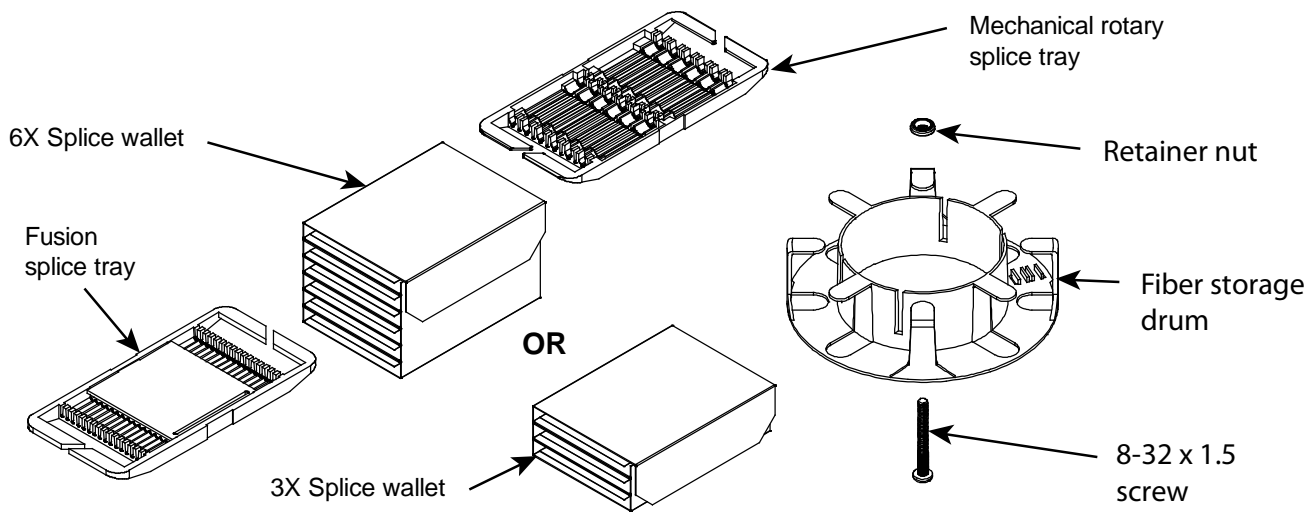

1. Verify parts in kit against those listed in table above.

## Step 2 – Mount Splice Wallet


**Note:** Splice wallet shall be mounted on a smooth, flat surface only. Orient as required for accessibility and easy fiber routing.

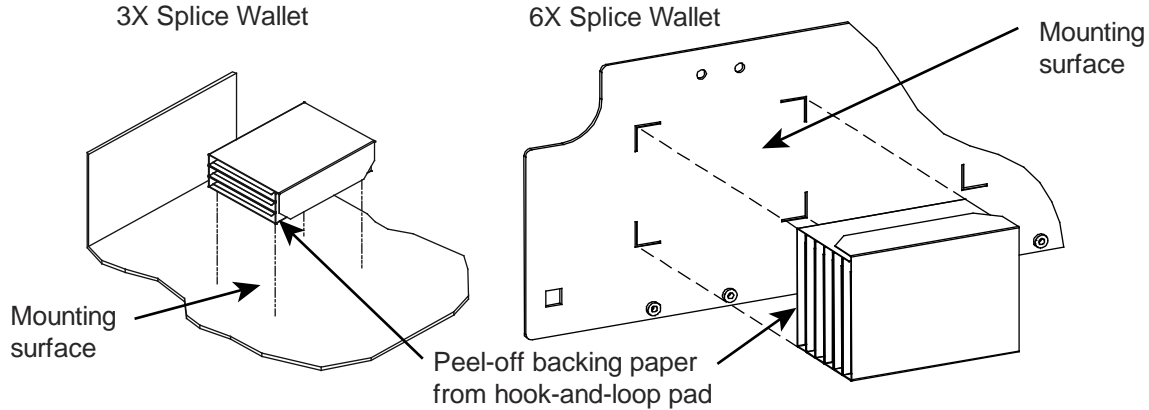

1. Wipe mounting surface with isopropyl alcohol and a lint-free cloth or tissue to clean and degrease.
2. Peel-off paper backing from hook-and-loop pad on base of splice wallet. Press splice wallet firmly into place and apply pressure for several seconds.

## Step 3 – Mount Splice Trays


**Note:** In order to function properly, all positions of the splice wallet must be populated with splice trays, whether or not they are to be used. Splice trays are mounted with adhesive pads provided on leaves of splice wallet.

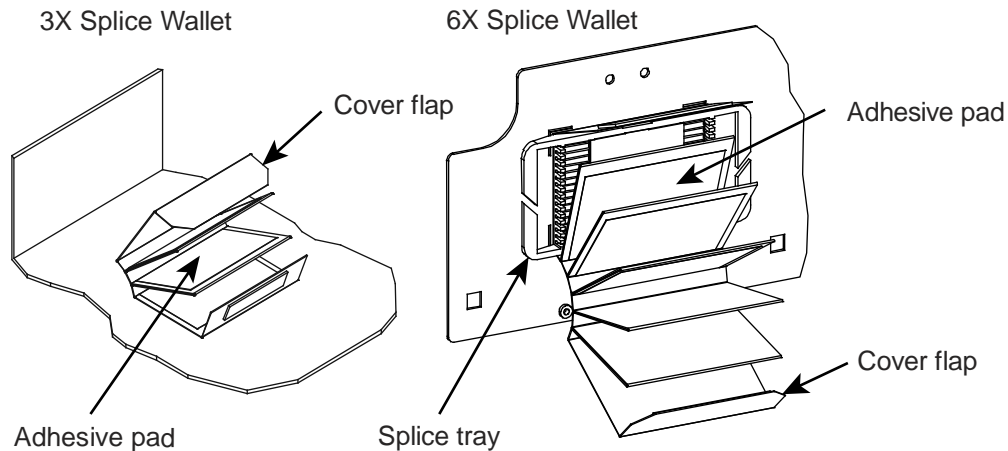

1. Wipe rear of splice tray with isopropyl alcohol and a lint-free cloth or tissue to clean and degrease.
2. Open cover flap of splice wallet and peel-off paper backing from an adhesive pad. Press splice tray firmly onto pad and apply pressure for several seconds.
3. Repeat above items for each remaining position in splice wallet.


**Note:** Installer may wish to populate splice tray before attaching to splice wallet. Alternatively, splice wallet may be temporarily removed from mounting surface (by releasing the hook-and-loop fastener) for splicing operations.

## Step 4 – Mount Fiber Storage Drum(s)

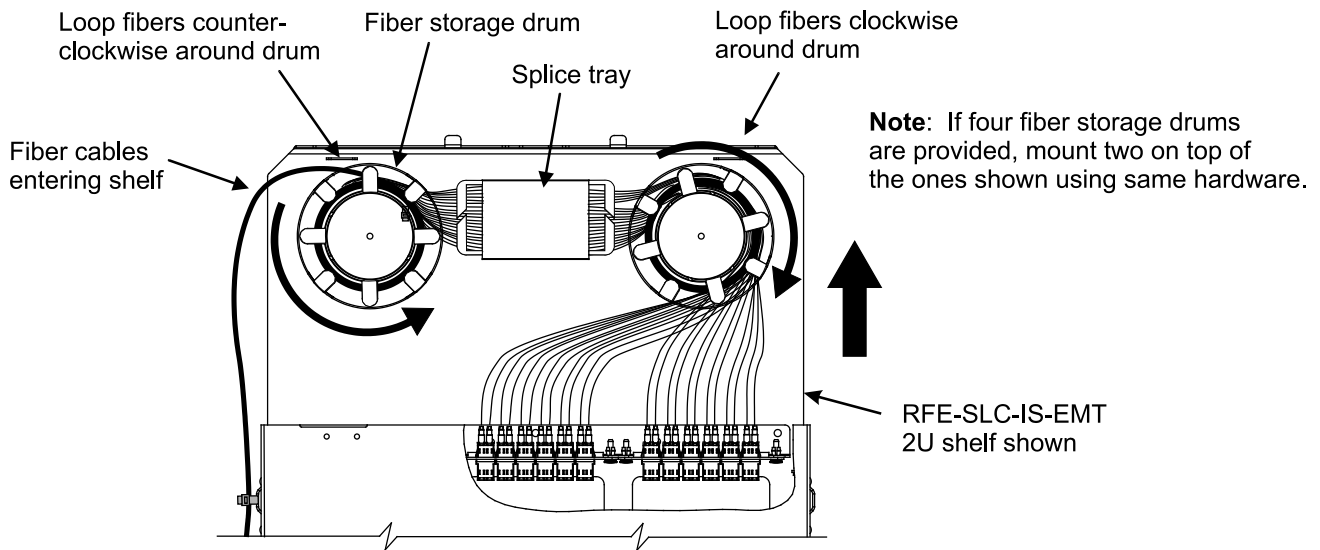

1. Pull internal sliding tray to the full rear position.
2. Locate fiber drum(s) on either side of splice wallet as shown. Secure using the provided 8-32 X 1.5 screw and retainer nut. If four fiber storage drums are provided, mount two drums on top of the two shown above using same mounting screws and retainer nuts. Mounting holes are provided in the internal sliding shelf.
3. The above figure shows a typical completed installation using two fiber drums and splice wallet mounted in a RFE-SLC-IS-EMT 2U internal sliding shelf.

## Step 5 – Close Splice Wallet and Secure

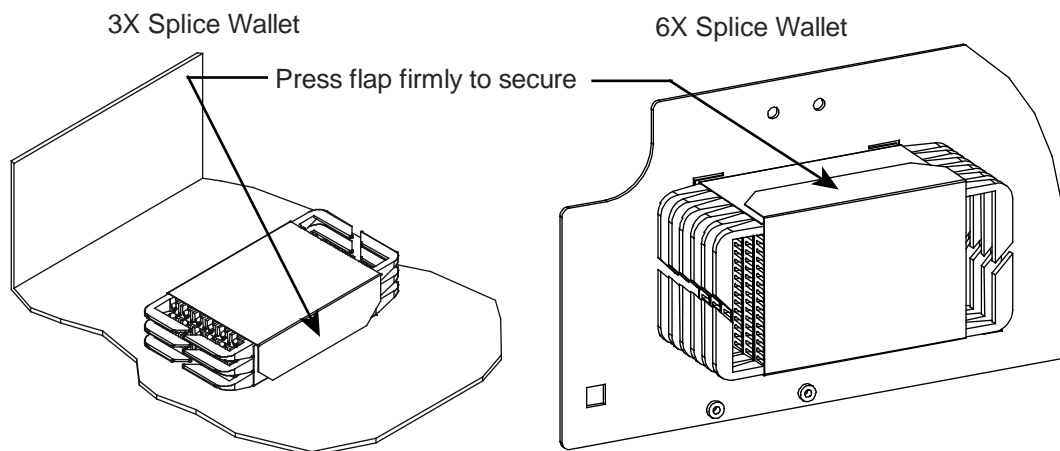

1. Close splice wallet cover and align hook-and-loop fasteners before pressing cover flap firmly to secure.