


760249633

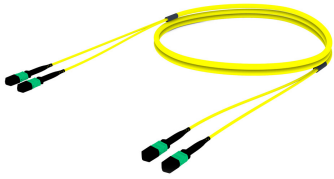

Low Tolerance length Singlemode MPO (Male) to MPO (Male) trunk, 24-Fiber, Low Smoke Zero Halogen B2ca, 290MT

Product Classification

Regional Availability	Europe Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters

General Specifications

Color, boot A	Black
Color, connector A	Green
Color, boot B	Black
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Male
Interface, Connector B	MPO-12/APC Male
Jacket Color	Yellow
Polarity	Method B (LL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	24

Dimensions

Breakout Length	33 in
Cord Length	290 m 951.444 ft
Cable Assembly Length Tolerance	+1/-0 ft

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

760249633

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.652.D G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ROHS	Compliant
UK-ROHS	Compliant



Included Products

760239612 N-024-MP-8W-F12YL/B2	-	Fiber indoor cable, TeraSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 24 fibers, 12 fiber subunits, Singlemode G.652.D and G.657.A1, Gel-free, Feet jacket marking, Yellow jacket color, B2ca Flame rating
860366178	-	MPO12, LOW LOSS, MALE, Singlemode, GREEN, 3mm