


# FGS-MTRM-E

---

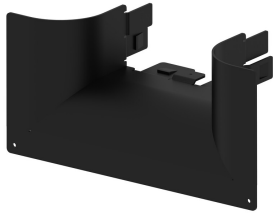

FiberGuide® Vertical Slotted Trumpet Flare, 4x2in, Black

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Trumpet flare
<b>Product Brand</b>	FiberGuide®
<b>Product Series</b>	FGS

## General Specifications

 
<b>Product Feature</b>	Slotted
<b>Color</b>	Black
<b>Orientation</b>	Vertical
<b>Section Type</b>	Vertical section

## Dimensions

<b>System Dimensions</b>	102 mm x 51 mm (4 in x 2 in)
--------------------------	------------------------------

## Ordering Tree

# FGS-MTRM-E



## Section Color

9	empty	yellow
	B	black

## Section Size

10	2A	4 x 6 in, for dual downspout
	2B-IMP	4 x 6 in, for dual downspout with divider
	A	4 x 4 in
	B	4 x 6 in
	C	2 x 2 in
	D	4 x 4 in, vertical
	DS	2 x 4 in, vertical
	E	2 x 4 in, vertical , black*
	F	4 x 12 in
	G	2 x 6 in
H	4 x 24 in, black*	

\* Only comes in black

## Material Specifications

**Material Type** Engineering Thermoplastic

## Environmental Specifications

**Flammability Rating** CSA S143 | UL 2024 | UL 94 V-0

**Halogen Characteristics** Blue Angel | TCO '99 | WEEE

**Safety Standard** CSA | UL

## Packaging and Weights

**Weight, net** 0.441 kg | 0.972 lb

## Regulatory Compliance/Certifications

### Agency

CHINA-ROHS

REACH-SVHC

ROHS

UK-ROHS

### Classification

Below maximum concentration value

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

Compliant

Compliant

