


RWPS wraparound pressure feeding sleeve heat shrink kit, pressurized, for 20 to 65 mm cable diameter, 250 mm long

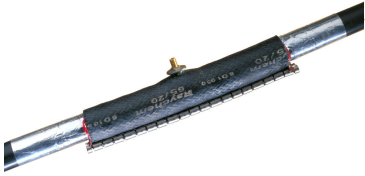

- Product can be used immediately after cooling down to ambient temperature
- Sleeve kit with incorporated pressure access point for all types of pressurized cables

OBSOLETE

This product was discontinued on: June 30, 2022

Product Classification

Regional Availability	EMEA
Product Type	Heat shrink repair sleeve
Product Series	RWPS

General Specifications

Color	Black
Sealant Type	Hotmelt adhesive

Dimensions

Length	250 mm 9.843 in
Expanded Inside Diameter, minimum	65 mm 2.559 in
Recovered Inside Diameter, maximum	20 mm 0.787 in
Single Cable Diameter, maximum	65 mm 2.559 in
Single Cable Diameter, minimum	20 mm 0.787 in

Material Specifications

Material Type	Fiber-reinforced multi-layer sealing sleeve
----------------------	---

Environmental Specifications

Environmental Space	Buried Ducted
----------------------------	-----------------

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

