

MC-SA12-B



Stand-off Arm with U-bolts, 12 in

Product Classification

Product Type Support arms for ring mount

General Specifications

Mounting Ring mount

Pipe, quantity 0

Dimensions

Height 254 mm | 10 in


Width 254 mm | 10 in

Length 304.8 mm | 12 in


Stand-off Distance 304.8 mm | 12 in

Outline Drawing

MC-SA12-B

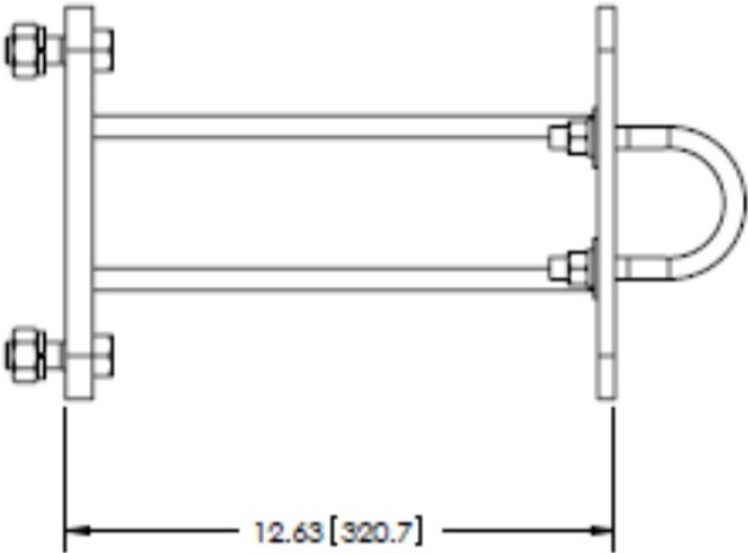

MC-SA12-B

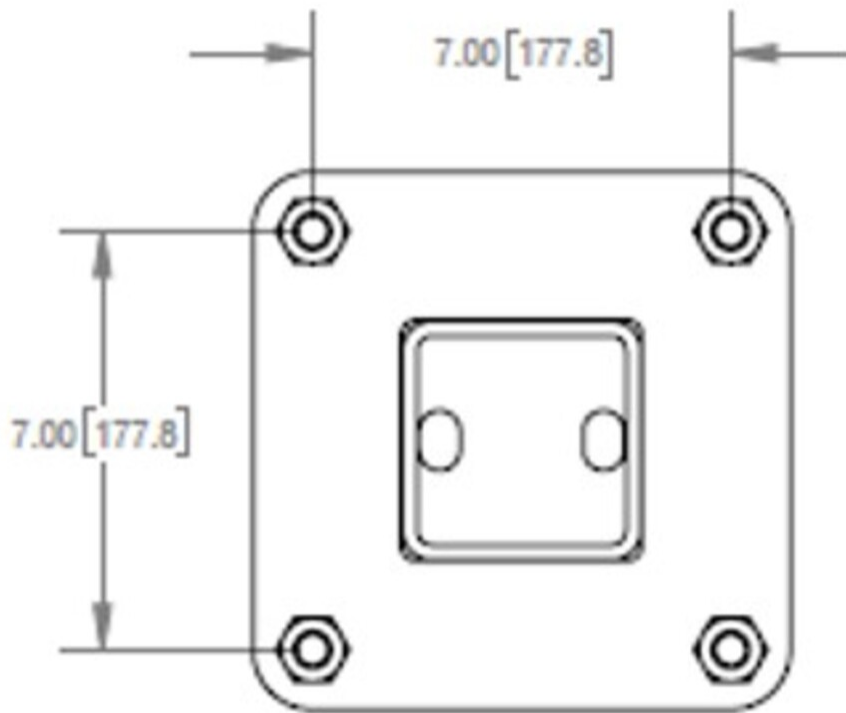

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating For Specifications, please contact steelproducts@commscope.com or call 800-255-1479

Wind Rating Criteria One 72 in x 8 in panel antenna per sector

Wind Rating Test Method TIA/EIA-222-G

Packaging and Weights

Included Hardware | Stand-off arms | U-bolts

Packaging quantity 1

Weight, net 34.24 kg | 75.486 lb

Regulatory Compliance/Certifications

Agency	Classification
--------	----------------

MC-SA12-B

CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code