 


MTC401560HC



H-Frame with Ice Canopy, 5ft long with 2 Posts

Product Classification

Product Type Ice canopies and shields

Dimensions

Height 4,076.7 mm | 160.5 in

Width 1524 mm | 60 in

Length 1,460.5 mm | 57.5 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Hardware | Ice shield | Legs | Unistrut

Packaging quantity 1

Weight, net 147.6 kg | 325.402 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted



Included Products

MF-130 – Direct Burial Pipe Column, 13 ft 4 in

MF-130



Direct Burial Pipe Column, 13 ft 4 in

Product Classification

Product Type Pipe column

General Specifications

Application Direct burial

Mounting Waveguide bridge support bracket

Pipe, quantity 1

Dimensions

Height 4064 mm | 160 in

Width 88.9 mm | 3.5 in


Length 88.9 mm | 3.5 in

Pipe Length 4,053.84 mm | 159.6 in

Pipe Outer Diameter 88.9 mm | 3.5 in

MF-130

Outline Drawing

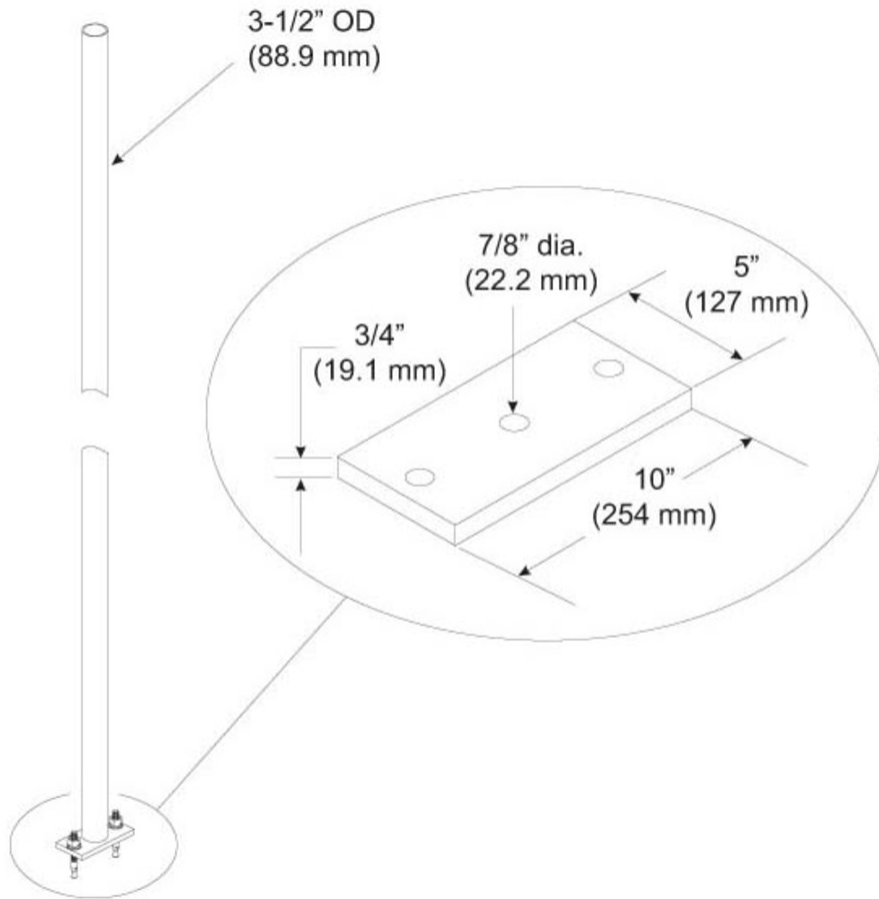

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Anchors | Pipe

Packaging quantity 1

Weight, net 45.8 kg | 100.972 lb

Regulatory Compliance/Certifications

Agency **Classification**

MF-130

CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

