

FJ-2SM-015A2N

HELIAX® Discrete tail, 2 single mode fiber, armored, Top/Bottom:
Ruggedized DLC with fiber weatherproof shroud



Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Wireless Fiber Cable Assemblies
Product Brand	HELIAX®
Product Series	FJ
Ordering Note	CommScope® non-standard product

General Specifications


Construction Type	Direct fiber tail
Interface, Connector A	DLC
Interface Feature, connector A	Outdoor
Interface, Connector B	DLC
Interface Feature, connector B	Outdoor
Jacket Color	Black
Total Fibers, quantity	2

Dimensions

Cable Assembly Length Range (m)	0.8 – 10
Diameter Over Jacket	2.5 mm 0.098 in

Ordering Tree

FJ-2SM-015A2N

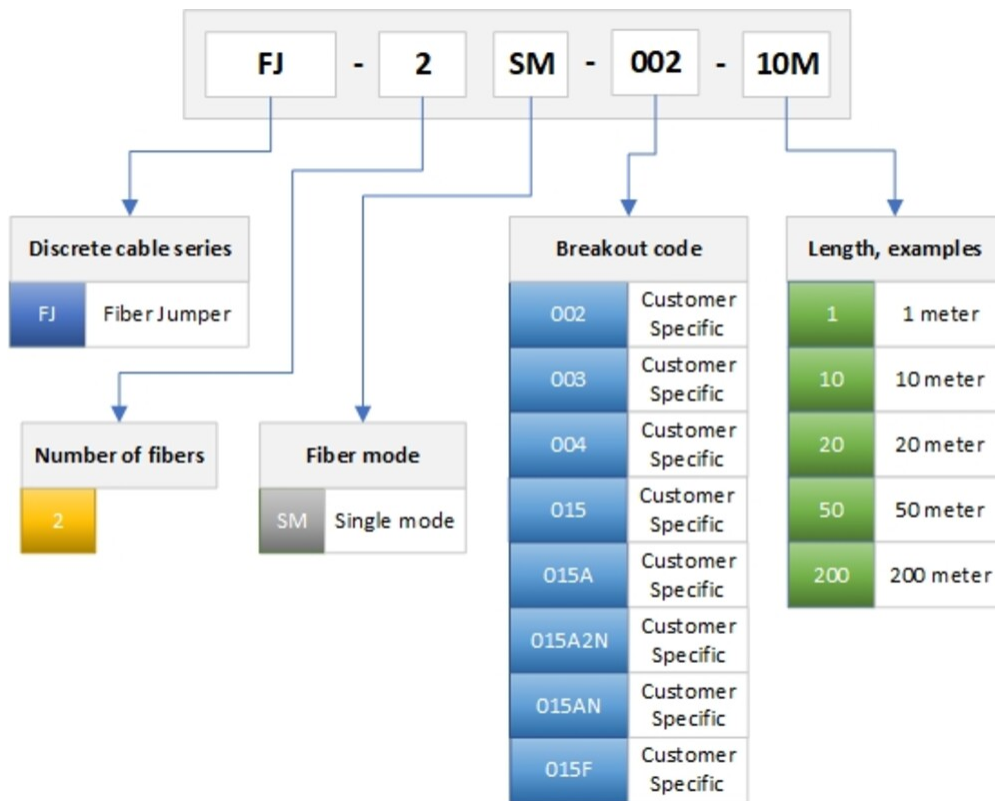

Optical Specifications

Fiber Type	G.657.A2
Insertion Loss, typical note	Insertion loss is measured at 1310 and 1550 nm
Insertion Loss, typical	0.5

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Environmental Space	Outdoor

Packaging and Weights

Cable weight	4.2 kg/km 2.822 lb/kft
---------------------	--------------------------

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

FJ-2SM-015A2N

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant



* Footnotes

Insertion Loss, typical note Insertion loss is measured at a room temp of +20°C (+68°F)