


C-LN

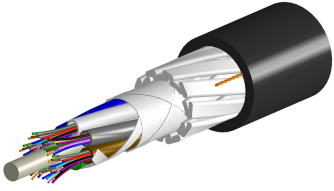

Fiber Optic Cable, Indoor/outdoor Low Smoke Zero Halogen, CPR-only flame rated, Stranded Loose Tube All-Dielectric

- Indoor/outdoor cables are tough enough for outdoor use while also being listed for indoor use
- Superior mechanical and optical performance with unmatched stability and quality
- Available Jacket Colors: Aqua, Black and Yellow

Product Classification


Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber indoor/outdoor cable
Product Series	C-LN
Ordering Note	Available cable jacket colors: aqua,black, yellow

General Specifications

Cable Type	Stranded loose tube
Construction Type	All Dielectric Non-armored
Jacket Marking	Custom printing Feet Meters

C-LN

Ordering Tree

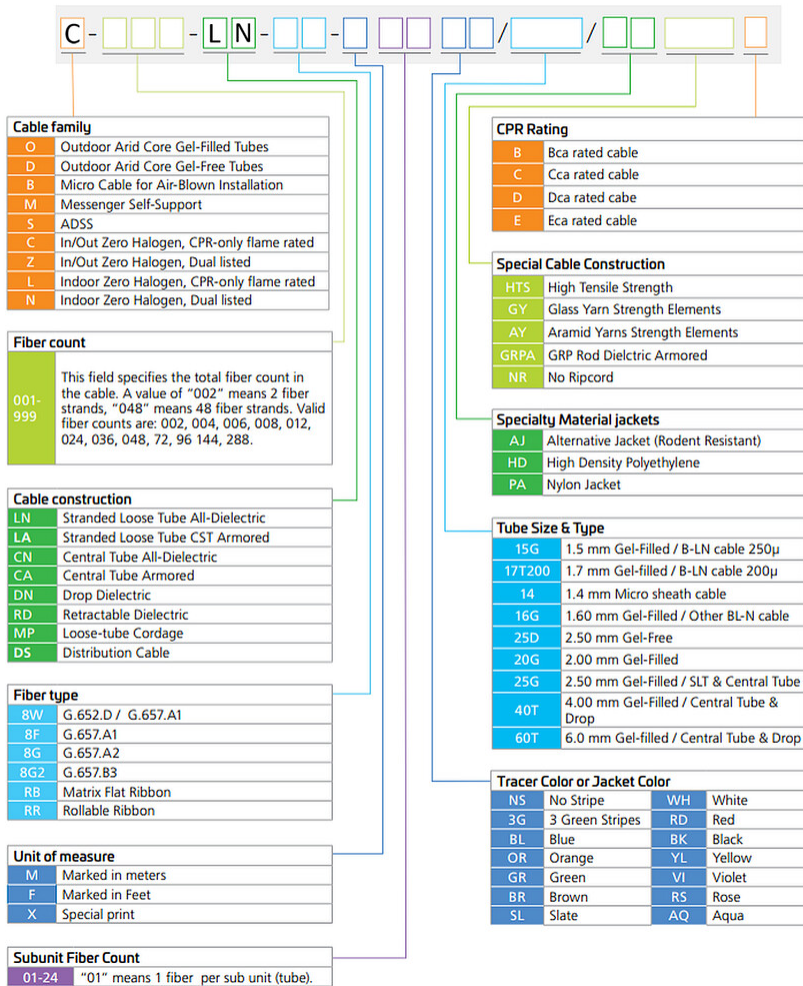

Environmental Specifications

Installation temperature	-30 °C to +60 °C (-22 °F to +140 °F)
Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +75 °C (-40 °F to +167 °F)
Environmental Space	Low Smoke Zero Halogen (LSZH)

* Footnotes

Operating Temperature Specification applicable to non-terminated bulk fiber cable