


MC-PM10M-12C-96

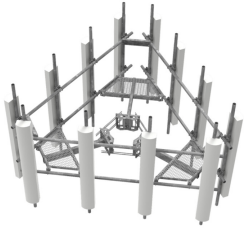

ATLAS 10 ft Monopole Platform with (12) 2.88" OD x 96" Antenna Pipes. Includes Top Rail Kit.

The innovative ATLAS Monopole Platform provides high-load performance, Lower EPA, and reduced weight – all with a single-point tower connection.

NOTE: Engineering loading based on Antenna pipes vertically centered on main horizontal face.

Product Classification

Product Type	Monopole platform kit
Product Series	ATLAS
Country Specific for	United States

General Specifications

Mounting	Monopole, 304.8–1270 mm (12–50 in) OD
Pipe, quantity	12
Sectors, quantity	3

Dimensions

Height	2,438.4 mm 96 in
Face Width	36.576 m 120 ft
Platform Width	3,200.4 mm 126 in
Pipe Length	2,438.4 mm 96 in
Face Support Pipe Diameter	73.025 mm 2.875 in
Pipe Outer Diameter	73.025 mm 2.875 in
Mounting Circumference, maximum	1,143 mm 45 in
Mounting Circumference, minimum	304.8 mm 12 in

Mechanical Specifications

Wind Rating	For Specifications, please contact steelproducts@commscope.com or call 800-255-1479
--------------------	--------------------------------------------------------------------------------------------------------------------------------------

Packaging and Weights

Included	Mounting hardware Plain end pipes (12) Platform Rail Ring mount
-----------------	-------------------------------------------------------------------------

MC-PM10M-12C-96

Weight, net 986.11 kg | 2174 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code