


BLK-RLBT-A02050

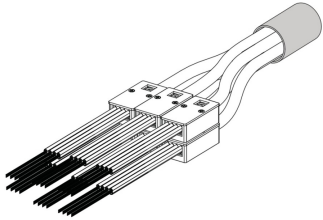

Fiber Optic Ribbon Breakout Kit, 12F/ribbon, 72F/tube, 5 breakout legs, 2 tubes/leg

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber breakout kit, rectangular
Product Series	BLK-R

General Specifications

Application	For use with ribbon fiber cables
Breakout Legs, quantity	5
Fibers per Ribbon, maximum	12
Fibers per Tube, maximum	72
Tube Type	Ribbon in loose buffer tube
Tubes per Leg, quantity	2

Dimensions

Tube Length	5,001.26 mm 196.9 in
--------------------	------------------------

Environmental Specifications

Environmental Space	Outdoor
----------------------------	---------

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

BLK-RLBT-A02050

UK-ROHS

Compliant

