

# NG4-CMDKKHQ

---



NG4access® Cabled Module, singlemode LC/UPC to LC/UPC, 144 fiber, stranded, IFC

- Cabled modules enable the routing of fiber cable to the frame, where multiple connectors are terminated to the frame with a single click
- Integrated connectors ensure the cables are kept in sequential order, and help prevent accidental fiber breakage or disruption to adjacent fibers during installation
- Available in a pigtail version for splicing on frame or preterminated to 24-fiber microcable or conventional IFC cable

## Product Classification

|                              |   |
|------------------------------|---|
| <b>Regional Availability</b> | Latin America   North America   |
| <b>Portfolio</b>             | CommScope®  |
| <b>Product Type</b>          | Fiber cabled module   |
| <b>Product Brand</b>         | NG4access®  |
| <b>Product Series</b>        | NG4   |
| <b>Ordering Note</b>         | For fiber modules with custom cable lengths, please contact your local CommScope representative |

## General Specifications


|                                     |                         |
|-------------------------------------|-------------------------|
| <b>Configuration Type</b>           | NG4 Module to Connector |
| <b>Adapters, quantity, front</b>    | 72                      |
| <b>Body Style</b>                   | Straight orientation    |
| <b>Cable Color</b>                  | Yellow                  |
| <b>Cable Type</b>                   | IFC - Stranded          |
| <b>Color, front</b>                 | Black                   |
| <b>Color, housing</b>               | Black                   |
| <b>Color, rear</b>                  | Black                   |
| <b>Interface, front</b>             | LC/UPC                  |
| <b>Interface, rear</b>              | LC/UPC                  |
| <b>Polarity</b>                     | Pairs, straight         |
| <b>Total Fibers, quantity</b>       | 144                     |
| <b>Total Ports, quantity, front</b> | 144                     |

# NG4-CMDKKHQ

## Dimensions

|               |                     |
|---------------|---------------------|
| <b>Height</b> | 13.3 mm   0.524 in  |
| <b>Width</b>  | 159.9 mm   6.295 in |
| <b>Depth</b>  | 101 mm   3.976 in   |

## Ordering Tree

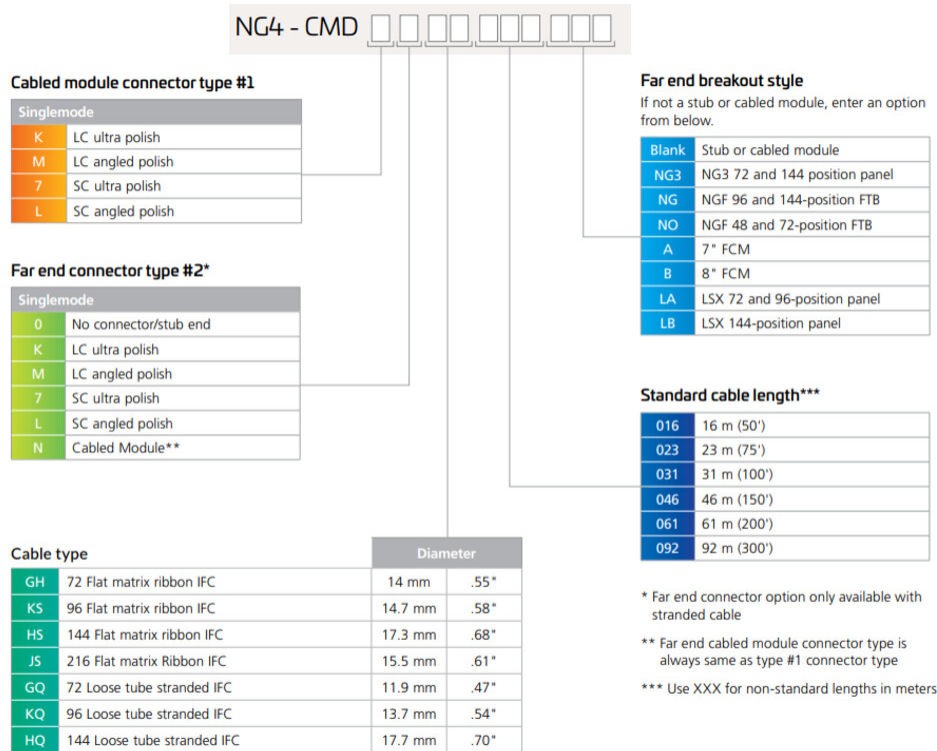

## Optical Specifications

|                   |            |
|-------------------|------------|
| <b>Fiber Mode</b> | Singlemode |
| <b>Fiber Type</b> | G.657.A2   |

## Environmental Specifications

|                              |                                      |
|------------------------------|--------------------------------------|
| <b>Operating Temperature</b> | -5 °C to +40 °C (+23 °F to +104 °F)  |
| <b>Storage Temperature</b>   | -40 °C to +70 °C (-40 °F to +158 °F) |
| <b>Relative Humidity</b>     | Up to 85%, non-condensing            |

# NG4-CMDKKHQ

---

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

### Agency

### Classification

CHINA-ROHS

Above maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant/Exempted

