

BTT-B8HF000000N000



BTT Tap Terminal, 8 Port, Hardened full size, butt type, terminating configuration, black

- Full and terminating tap versions
- Available in both butt and Inline configurations
- Available in both black and gray housing color
- Color coded ports for identification easiness

Product Classification

Regional Availability	Latin America
Product Type	Access terminal, with tap
Product Series	BTT
Minimum Order Quantity	1

General Specifications


Cable Type	No cable (stubless)
Cable, quantity	8
Distribution Type	8-port tap
Drop Port Type	Hardened full-size SC/APC
Enclosure Color	Black
Input Tap, quantity	1
Mounting	Handhole Pedestal Pole Strand
Port Type	Hardened full-size SC/APC
Port, quantity	9
Split Ratio	Terminating
Splitter, quantity	1
Stub Type	No tail

Dimensions

Width	141 mm 5.551 in
Depth	90 mm 3.543 in
Length	258 mm 10.157 in
Cable Length, stub	0 ft (0 m)

BTT-B8HF000000N000

Port Configuration

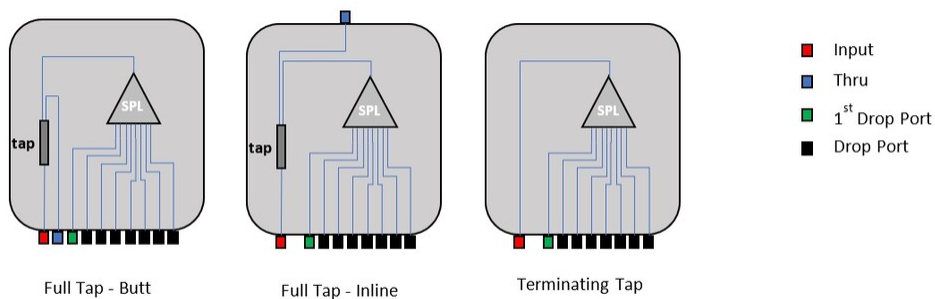

Ordering Tree

BTT - 8 H 0000 0 N 000

Color	Configuration	Type
B - Black	A - 90/10	0 - Butt
G - Gray	B - 85/15	1 - Inline
	C - 80/20	
	D - 70/30	
	E - 60/40	
	G - 50/50	
	F - Terminating	

Ordering example
 Hardened Full Tap, Black, Butt, 70/30 (BTT-B8H0D000000N000)

Material Specifications

Enclosure Material Type Glass filled polypropylene (GF-PP)

Optical Specifications

Fiber Type G.657.A2

Operating Wavelength Range 1260 – 1650 nm

Tap Drop Loss, maximum 10.5 dB

Environmental Specifications

Operating Temperature -30 °C to +70 °C (-22 °F to +158 °F)

Relative Humidity 0%–100%, condensing

Environmental Space Above ground | Below ground | Buried

BTT-B8HF000000N000

Qualification Standards Anatel

UV Resistance UV stabilized

Packaging and Weights

Packaging quantity 1

Packaging Type Box | Carton

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

