

U3XQVUCT8



Ultra Low Loss (ULL) OM4 MPO8 APC (Non-Pinned) to
Unconnectorized, Fiber Array Cable Assembly, 8-Fiber, LSZH B2ca

Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Gray
Color, connector A	Green
Connector A, quantity	1
Connector B, quantity	0
Construction Type	Stranded
Fibers per Subunit, quantity	8
Furcation Color	Aqua
Interface, Connector A	MPO-08/APC Female
Interface, Connector B	Unterminated
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	8

Dimensions

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

U3XQVUCT8

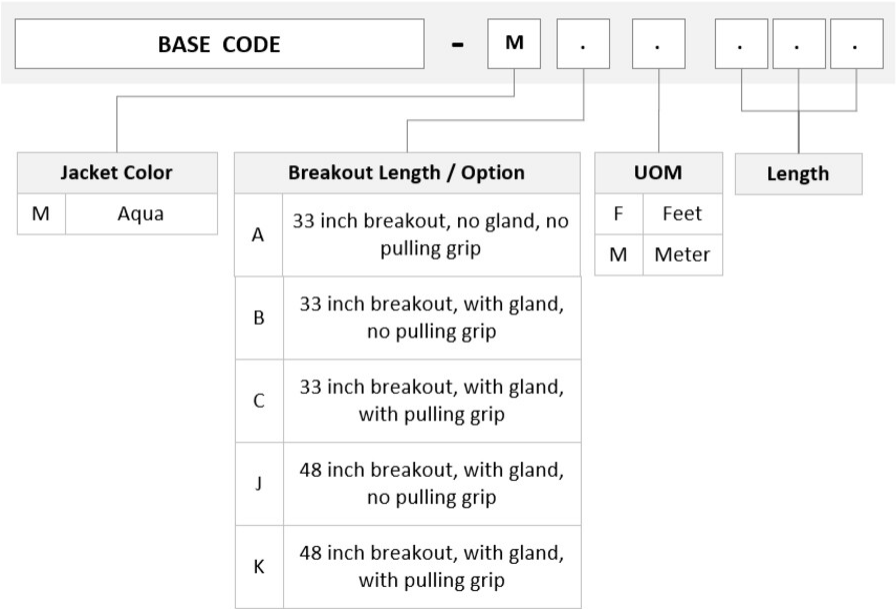

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance B2ca
Environmental Space Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

U3XQVUCT8



Included Products

- | | | |
|--------------------------|---|--|
| 760253116 | – | LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable with 2.0mm Subunits, 8 |
| N-008-MP-5K-F08AQ/20T/B2 | | fiber |
| 860662232 | – | MP08,ULL,Multimode,FEMALE,APC,GREEN,2 mm |