


UJVVQVQZTL

Base Product

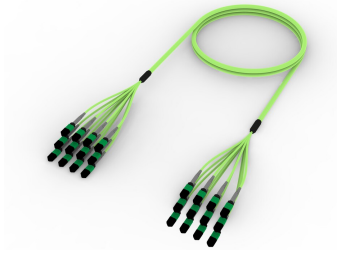

Ultra Low Loss (ULL) OM5 MPO APC (Non-Pinned) to MPO APC (Pinned), Fiber Trunk Cable Assembly, 96-Fiber, Dual Rated (OFNR /LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	12
Color, boot A	Gray
Color, connector A	Green
Connector B, quantity	12
Color, boot B	Gray
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-08/APC Female
Interface, Connector B	MPO-08/APC Male
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	96

Dimensions

UJVVQVQZTL

Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree



Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0° 4.40 lb @ 90°
--	-------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser Indoor

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

- | | | |
|--------------------------------------|---|---|
| 760248177
N-096-MP-5G-F08AQ/20T/D | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 96 fiber multi-unit with 8 fiber 2.0mm subunits, Gel-free, Multimode OM5, Feet jacket marking, Aqua jacket color, Dca flame rating |
| 860662230 | - | MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm |
| 860662232 | - | MPO8,ULL,Multimode,FEMALE,APC,GREEN,2 mm |