


# URXRVMXAH

## Base Product

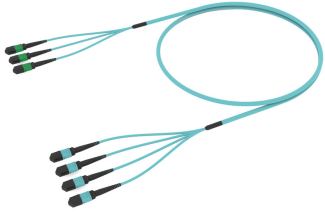

Ultra Low Loss (ULL) OM4, 3X4, MPO16 Multimode APC (Non-Pinned) to MPO12 (Pinned), 48-Fiber, Conversion Array, LSZH

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber conversion array cable assembly
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	3
<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Aqua
<b>Connector B, quantity</b>	4
<b>Color, boot B</b>	Gray
<b>Color, connector B</b>	Aqua
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-16/APC Female
<b>Interface, Connector B</b>	MPO-12/UPC Male
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	48

## Dimensions


<b>Breakout Length</b>	12 in   24 in   36 in   48 in   60 in   72 in
------------------------	---

# URXRVMXAH

**Cable Assembly Length Range (m)** 2 – 305

**Cable Assembly Length Range (ft)** 4 – 999

## Ordering Tree

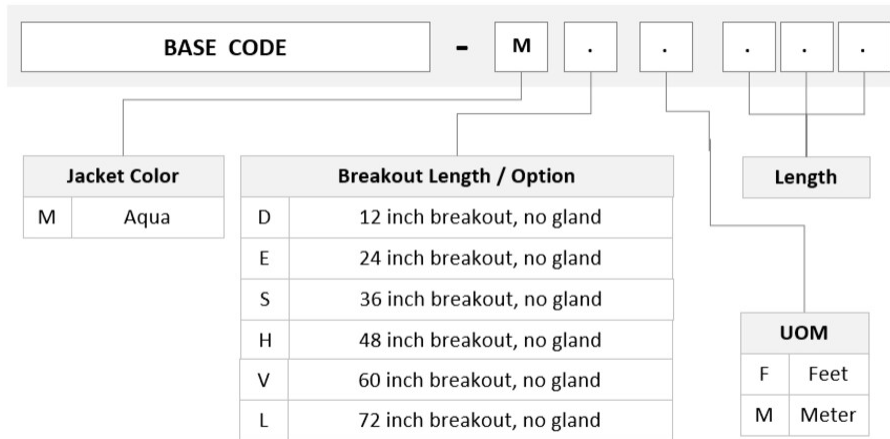

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# URXRVMXAH

---



## Included Products

- |                                  |   |  |
|----------------------------------|---|--|
| 760067496<br>N-048-MP-5K-F12AQ/D | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 48 fiber multi-unit with 12 fiber subunits, Gel-free, Multimode OM4, Feet jacket marking, Aqua jacket color, Dca flame rating |
| 860366228                        | - | MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm  |
| 860659159                        | - | Fiber Optic Connector Kit, multimode, OM3/OM4, MPO-16/APC, ULL, non-pinned, green, for 3 mm cable  |