


760253737 | PPL-DM-16AU-8SN-SM-SAMPLE

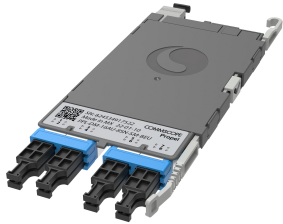

Propel Sample Singlemode MPO-16 Distribution Module, 8SN to 1X16f MPO, No fiber

- Can be installed and removed from front or rear of panel
- This component requires 2 of the 12 lanes on the Propel Panel blade

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	SYSTIMAX®
Product Type	Breakout module
Product Brand	Propel
Product Series	PPL

General Specifications

Functionality	Breakout
Color, front	Blue
Color, rear	Gray
Interface, front	SN/UPC
Interface Feature, front	Dust caps
Interface, rear	MPO
Interface Feature, rear	Dust caps
Total Fibers, quantity	0
Total Ports, quantity, front	8
Total Ports, quantity, rear	1

Dimensions

Height	11 mm 0.433 in
Width	131 mm 5.157 in
Depth	170 mm 6.693 in

Optical Specifications

Insertion Loss, maximum	dB
--------------------------------	----

Environmental Specifications

Safety Standard CE | CSA | UL 62368

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

