


# MC-CP14M-B

---

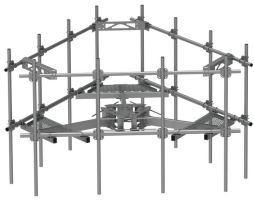

3-Sector Monopole Co-location Platform Base Kit, 12 in to 50 in OD, 14 ft 6 in face, pipe ordered separately

## Product Classification

**Product Type** Co-location platform

## General Specifications

**Mounting** Monopole, 304.8–1270 mm (12–50 in) OD

**Pipe, quantity** 0

**Sectors, quantity** 3

## Dimensions

**Face Width** 4.42 m | 14.5 ft

**Width** 4,419.6 mm | 174 in

**Mounting Diameter, maximum** 1270 mm | 50 in

**Mounting Diameter, minimum** 304.8 mm | 12 in

**Pipe Outer Diameter** 60.96 mm | 2.4 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating** 120 mph (BWS) at 100 ft AGL | 140 mph (3-second gust) at 150 ft AGL using Exposure D per FBC

**Wind Rating Test Method** TIA/EIA-222

## Packaging and Weights

**Included** Platform | Rail | Ring mount

**Packaging quantity** 1

# MC-CP14M-B

---

**Weight, net** 665.284 kg | 1,466.7 lb

\* Footnotes

**Wind Rating** BWS—Base Wind Speed; FBC—Florida Building Code