


MC-PK14S4-B

4-Sector Monopole Co-location Platform kit, 10 in to 30 in OD, 14 ft 6 in face, pipe ordered separately

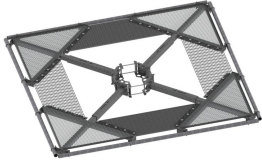

Product Classification

Product Type Monopole platform kit

General Specifications

Mounting Monopole, 254–762 mm (10–30 in) OD

Pipe, quantity 0

Dimensions

Height 254 mm | 10 in
Face Width 4.42 m | 14.5 ft
Width 4,419.6 mm | 174 in
Length 914.4 mm | 36 in
Face Support Pipe Diameter 88.9 mm | 3.5 in
Mounting Diameter, maximum 762 mm | 30 in
Mounting Diameter, minimum 254 mm | 10 in
Pipe Outer Diameter 0 mm | 0 in
Stand-off Distance 914.4 mm | 36 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating Test Method TIA/EIA-222

Environmental Specifications

MC-PK14S4-B

EPA with 1/2 in (12 mm) radial ice 3.182 m² | 34.25 ft²

EPA without ice 2.576 m² | 27.73 ft²

Packaging and Weights

Included Platform | Ring mount

Packaging quantity 1

Weight, net 1,154.347 kg | 2,544.9 lb

* Footnotes

EPA with 1/2 in (12 mm) radial ice EPA—Effective Projected Area

EPA without ice EPA—Effective Projected Area