


# MC-RM1550-3

---

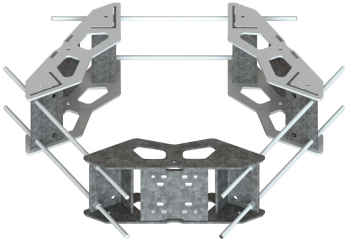

Universal Ring Mount, 15 in to 50 in OD

## Product Classification

**Product Type** Universal ring mount

## General Specifications

**Mounting** Monopole, 381–1270 mm (15–50 in) OD

**Pipe, quantity** 0

**Sectors, quantity** 3

## Dimensions

**Height** 254 mm | 10 in

**Length** 152.4 mm | 6 in

**Mounting Diameter, maximum** 1270 mm | 50 in

**Mounting Diameter, minimum** 381 mm | 15 in


**Pipe Outer Diameter** 0 mm | 0 in

**Mounting Circumference, maximum** 3,990.34 mm | 157.1 in

**Mounting Circumference, minimum** 1,196.34 mm | 47.1 in

# MC-RM1550-3

## Outline Drawing

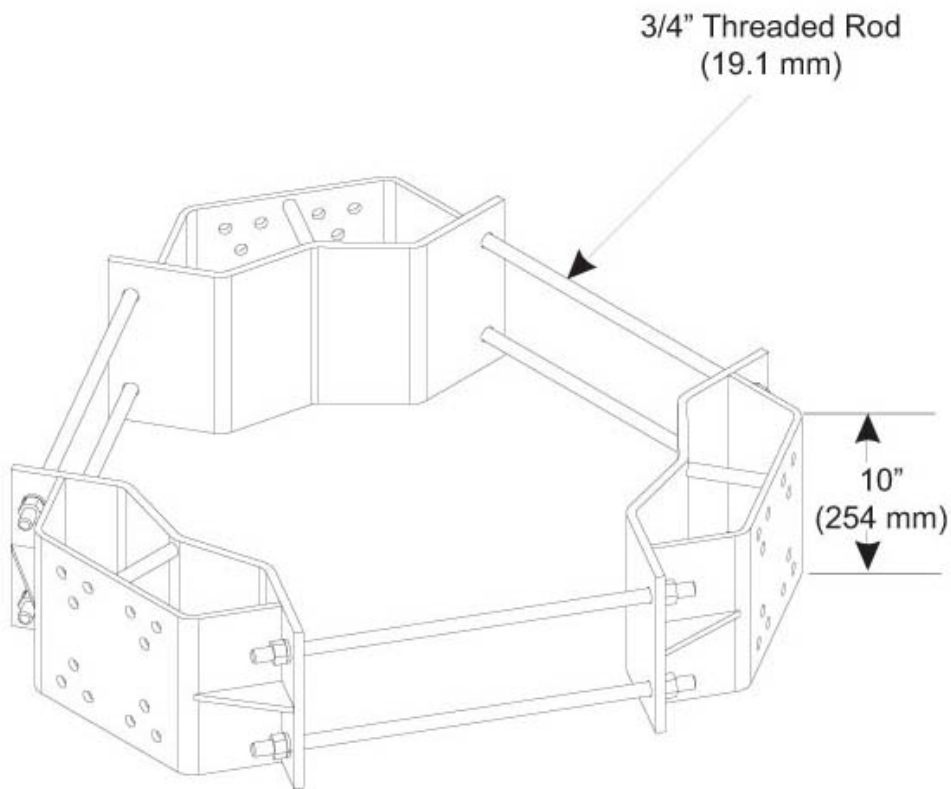

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating** 140 mph (BWS) at 150 ft AGL | 160 mph (3-second gust) at 150 ft AGL using Exposure D per FBC

**Wind Rating Criteria** Four 72 in x 8 in panel antennas per sector

**Wind Rating Test Method** TIA/EIA-222

## Packaging and Weights

**Included** Mount | Threaded rod

**Packaging quantity** 1

**Weight, net** 117.934 kg | 260 lb

# MC-RM1550-3

---

## Regulatory Compliance/Certifications

**Agency**

CHINA-ROHS

ISO 9001:2015

ROHS

UK-ROHS

**Classification**

Above maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant/Exempted

Compliant/Exempted

### \* Footnotes

**Wind Rating**

BWS—Base Wind Speed; FBC—Florida Building Code