


U4XQZLUTU

Base Product

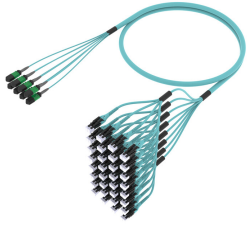

Ultra Low Loss ULL OM4 MPO8 APC pinned to LC/UPC Uniboot Ruggedized fanout Cable, 64-Fiber, LSZH, 8 fiber PmP 2.0 mm /B2ca

Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Connector A, quantity	8
Color, boot A	Gray
Color, connector A	Aqua
Connector B, quantity	64
Color, boot B	Aqua
Color, connector B	Black
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/APC Male
Interface, Connector B	LC/UPC
Interface Feature, connector B	Uniboot
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	64

Dimensions

U4XQZLUTU

Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

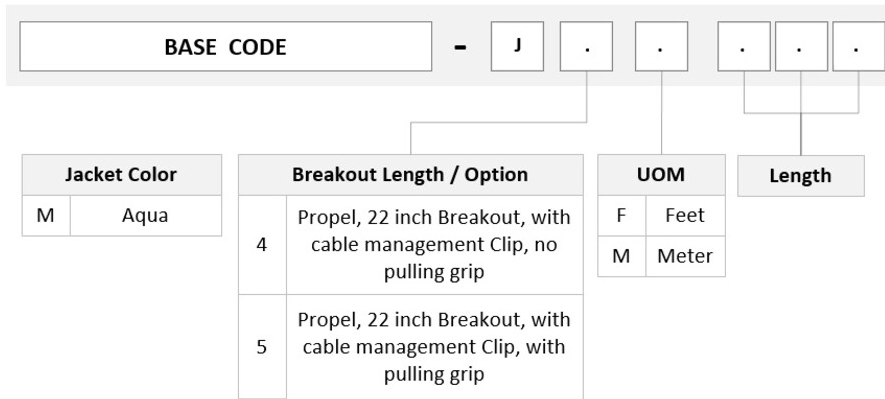

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance B2ca

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted

U4XQZLUTU

UK-ROHS

Compliant/Exempted



Included Products

- | | | |
|---------------------------------------|---|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| 760253121
N-064-MP-5K-F08AQ/20T/B2 | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk with 2.0mm Subunits, 64 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating |
| 860658161 | - | 2.0 mm LC/UPC Uniboot GEN 1.5, Aqua |
| 860662230 | - | MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm |