


Base Product

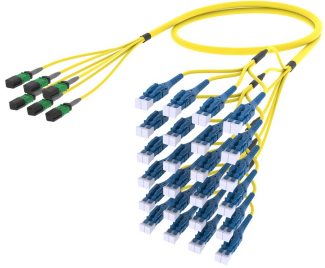

Singlemode MPO8 APC pinned to LC/UPC Uniboot Ruggedized fanout Cable, 48-Fiber, Dual Rated (OFNR/LSZH), 8 fiber PmP 2.0 mm

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	6
Color, boot A	Gray
Color, connector A	Green
Connector B, quantity	48
Color, boot B	Blue
Color, connector B	Blue
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-08/APC Male
Interface, Connector B	LC/UPC
Interface Feature, connector B	Uniboot
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	48

UNGQXLUTH

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted



Included Products

- 760245573
N-048-MP-8G1-F08YL/20T/D – Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 48 fiber multi-unit with 8 fiber 2.0 mm subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating
- 860658160 – LC/UPC Uniboot Connector, Singlemode, Blue
- 860659022 – MPO-08, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm