


UKVQZQZTF

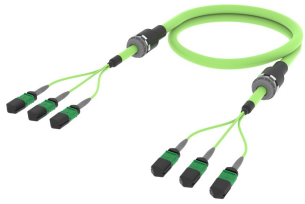

Ultra Low Loss (ULL) OM5 MPO8 APC (pinned) to MPO8 APC (pinned) Fiber Trunk Cable Assembly, 24-Fiber, Armored Indoor Dual Rated (OFNR /LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	3
Color, boot A	Gray
Color, connector A	Green
Connector B, quantity	3
Color, boot B	Gray
Color, connector B	Green
Construction Type	Armored Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-08/APC Male
Interface, Connector B	MPO-08/APC Male
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	24

Dimensions


Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305

UKVQZQZTF

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

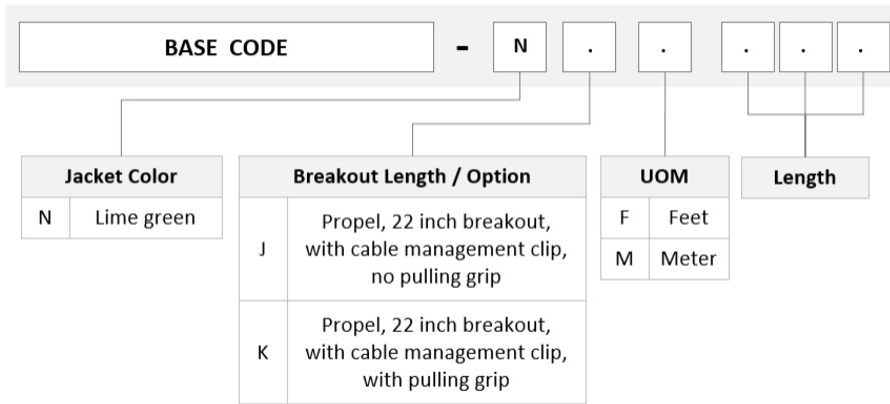

Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode

Multimode

Fiber Type

OM5, LazrSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance

Dca

Environmental Space

Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

UKVQZQZTF



Included Products

- 760256035
N-024-MZ-5G-F08LM/20T/B2
 - 860662230
- Fiber indoor cable, Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM5, 24 fiber, Gel-free, Feet jacket marking, Lime green jacket color, B2ca flame rating
 - MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm