


MTC3914M3

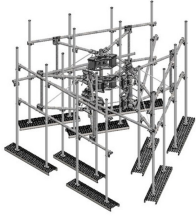

G22 High Capacity 3-Sector Monopole Frame with Work Platform, 10 ft 6 in face, includes twelve 126 in pipes; For patents, see www.cs-pat.com.

OBSOLETE

This product was discontinued on: July 29, 2022

Product Classification

Product Type High capacity monopole sector frame

General Specifications

Mounting Monopole, 304.8–1270 mm (12–50 in) OD
Pipe, quantity 12
Sectors, quantity 3

Dimensions

Height 3,200.4 mm | 126 in
Face Width 3.2 m | 10.5 ft
Width 3,200.4 mm | 126 in
Pipe Length 3,200.4 mm | 126 in
Face Support Pipe Diameter 60.325 mm | 2.375 in
Mounting Diameter, maximum 1270 mm | 50 in
Mounting Diameter, minimum 304.8 mm | 12 in
Pipe Outer Diameter 60.325 mm | 2.375 in
Stand-off Distance 1,117.6 mm | 44 in
Mounting Circumference, maximum 1270 mm | 50 in
Mounting Circumference, minimum 304.8 mm | 12 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

MTC3914M3

Wind Rating	For Specifications, please contact your local ANDREW representative
Wind Rating Test Method	TIA/EIA-222

Packaging and Weights

Included	Pipe mounts Plain end pipes (12) Platform Ring mounts (2) Sector frames (3) Stiff arm
Packaging quantity	1
Weight, net	1,225.607 kg 2702 lb

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
--------------------	--