


# UKXQZQZTR

## Base Product

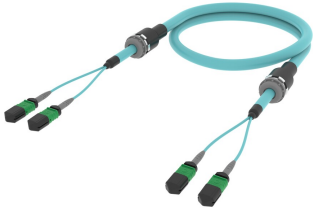

Ultra Low Loss (ULL) OM4 MPO8 APC (pinned) to MPO8 APC (pinned) Fiber Trunk Cable Assembly, 16-Fiber, Armored Indoor Dual Rated (OFNR /LSZH)

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Product Brand

Propel | SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Connector A, quantity

2

### Color, boot A

Gray

### Color, connector A

Green

### Connector B, quantity

2

### Color, boot B

Gray

### Color, connector B

Green

### Construction Type

Armored | Stranded

### Furcation Color

Aqua

### Interface, Connector A

MPO-08/APC Male

### Interface, Connector B

MPO-08/APC Male

### Jacket Color

Aqua

### Polarity

Method B Enhanced (ULL)

### Fibers per Subunit, quantity

8

### Total Fibers, quantity

16

## Dimensions

### Breakout Length

22 in

# UKXQZQZTR

<b>Cable Assembly Length Range (m)</b>	3 – 305
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree



## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0°   4.40 lb @ 90°
--	-------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Fiber Type</b>	OM4, LazrSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>EN50575 CPR Cable EuroClass Fire Performance</b>	Dca
<b>Environmental Space</b>	Dual Rated LSZH/Riser   Indoor

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# UKXQZQZTR

---



## Included Products

- 760256015  
N-016-MZ-5K-F08AQ/20T/B2 - Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, interlocking aluminum armored with low smoke zero halogen riser jacket, Multimode OM4, 16 fiber, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating
- 860662230 - MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm