


# UKXQZUCTF

---

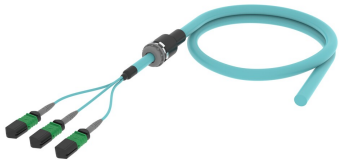

Ultra Low Loss (ULL) OM4 MPO8 APC (pinned) to Unconnectorized Fiber Trunk Cable Assembly, 24-Fiber, Armored Indoor Dual Rated (OFNR /LSZH)

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	3
<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Green
<b>Connector B, quantity</b>	0
<b>Construction Type</b>	Armored   Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-08/APC Male
<b>Interface, Connector B</b>	Unterminated
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	24

## Dimensions

<b>Breakout Length</b>	22 in
<b>Cable Assembly Length Range (m)</b>	3 – 305
<b>Cable Assembly Length Range (ft)</b>	10 – 999



# UKXQZUCTF

---

## Included Products

- 760256016  
N-024-MZ-5K-F08AQ/20T/B2
  - 860662230
- Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM4, 24 fiber, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating
  - MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm