


FQWMPMPHF

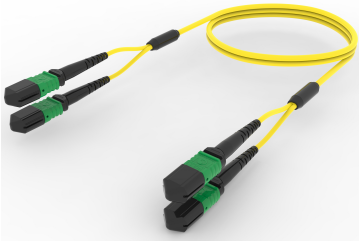

Singlemode, MPO/12(Unpinned) to MPO/12(Unpinned), InstaPATCH® 360 Array Cord, 24-Fiber, Plenum

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber array cable assembly

Product Brand

SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Black

Color, connector A

Green

Color, boot B

Black

Color, connector B

Green

Construction Type

Stranded

Furcation Color

Yellow

Interface, Connector A

MPO-12/APC Female

Interface Feature, connector A

Unpinned

Interface, Connector B

MPO-12/APC Female

Interface Feature, connector B

Unpinned

Jacket Color

Yellow

Polarity

Method B (LL)

Fibers per Subunit, quantity

12

Total Fibers, quantity

24

Dimensions


Cable Assembly Length Range (m)

3 – 305

FQWMPMPHF

Cable Assembly Length Range (ft) 10 – 999
Diameter Over Jacket 3.6 mm | 0.142 in

Ordering Tree

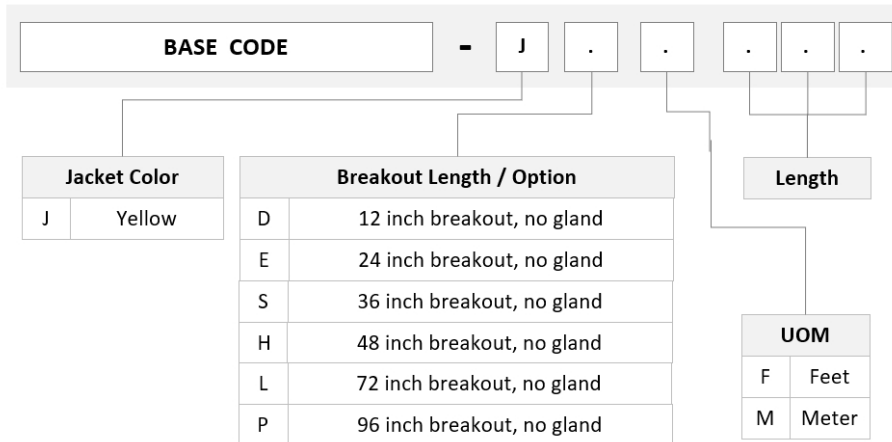

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

FQWMPMPHF



Included Products

- 760245873
P-024-MP-8G1-F36YL
 - 860638318
- Fiber indoor cable, Plenum for MPO Light Duty Patchcords, 24 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color
 - MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm