


# RK-36-4L

---

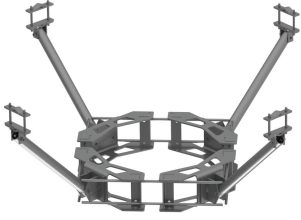

Monopole Load Distribution Reinforcement Kit, 4 Sector, 30" to 60" OD, 36" Kicker

## Product Classification

**Product Type** Reinforcement kit

## General Specifications

**Mounting** Monopole, 762–1524 mm (30–60 in) OD

**Sectors, quantity** 4

## Dimensions

**Height** 254 mm | 10 in

**Length** 914.4 mm | 36 in

**Mounting Diameter, maximum** 1524 mm | 60 in

**Mounting Diameter, minimum** 762 mm | 30 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating** For Specifications, please contact your local ANDREW representative

## Packaging and Weights

**Included** Attachment hardware | Ring mount

**Packaging quantity** 1

**Weight, net** 186.426 kg | 411 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>

# RK-36-4L

---

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted



## \* Footnotes

### **Wind Rating**

BWS—Base Wind Speed; FBC—Florida Building Code