


RK-36-4L

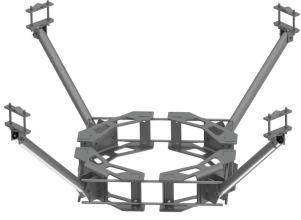

Monopole Load Distribution Reinforcement Kit, 4 Sector, 30" to 60" OD, 36" Kicker

Product Classification

Product Type Reinforcement kit

General Specifications

Mounting Monopole, 762–1524 mm (30–60 in) OD

Sectors, quantity 4

Dimensions

Height 254 mm | 10 in

Length 914.4 mm | 36 in

Mounting Diameter, maximum 1524 mm | 60 in

Mounting Diameter, minimum 762 mm | 30 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating For Specifications, please contact steelproducts@commscope.com or call 800-255-1479

Packaging and Weights

Included Attachment hardware | Ring mount

Packaging quantity 1

Weight, net 186.426 kg | 411 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

RK-36-4L

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted



* Footnotes

Wind Rating

BWS—Base Wind Speed; FBC—Florida Building Code