


# RK-36-4S

---

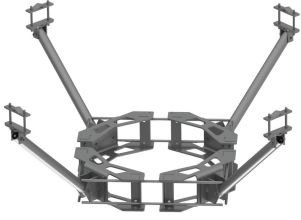

Monopole Load Distribution Reinforcement Kit, 4 Sector, 10" to 30" OD, 36" Kicker

## Product Classification

**Product Type** Reinforcement kit

## General Specifications

**Mounting** Monopole, 254–762 mm (10–30 in) OD

**Sectors, quantity** 4

## Dimensions

**Height** 254 mm | 10 in

**Length** 914.4 mm | 36 in

**Mounting Diameter, maximum** 762 mm | 30 in

**Mounting Diameter, minimum** 254 mm | 10 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating** For Specifications, please contact [steelproducts@commscope.com](mailto:steelproducts@commscope.com) or call 800-255-1479

## Packaging and Weights

**Included** Attachment hardware | Ring mount

**Packaging quantity** 1

**Weight, net** 131.995 kg | 291 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>

# RK-36-4S

---

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted



## \* Footnotes

### **Wind Rating**

BWS—Base Wind Speed; FBC—Florida Building Code