


# FGS-MH9E-M

---

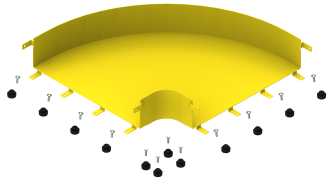

FiberGuide® 90° Horizontal Elbow, 4x18in, Yellow

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Elbow
<b>Product Brand</b>	FiberGuide®
<b>Product Series</b>	FGS

## General Specifications

<b>Angle/Bend Direction</b>	90°
<b>Color</b>	Yellow
<b>Orientation</b>	Horizontal
<b>Section Type</b>	Elbow section

## Dimensions

<b>Height</b>	120.14 mm   4.73 in
<b>Width</b>	476 mm   18.74 in
<b>Length</b>	614.43 mm   24.19 in
<b>System Dimensions</b>	102 mm x 457 mm (4 in x 18 in)

## Ordering Tree

# FGS-MH9E-M



## Section Color

9	empty	yellow
	B	black

## Section Size

1	A	4 x 4 in
0	B	4 x 6 in
	F	4 x 12 in
	F-VS	4 x 12 in , variable support bracket
	G	2 x 6 in
	M	4 x 18 in

\* Support brackets only come in black

## Material Specifications

**Material Type** Steel

## Environmental Specifications

**Flammability Rating** CSA S143 | UL 2024 | UL 94 V-0

**Halogen Characteristics** Blue Angel | TCO '99 | WEEE

**Safety Standard** CSA | UL

## Packaging and Weights

**Weight, net** 1.29 kg | 2.844 lb

## Regulatory Compliance/Certifications

### Agency

CHINA-ROHS

REACH-SVHC

ROHS

UK-ROHS

### Classification

Below maximum concentration value

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

Compliant

Compliant

