

TFP-ADAPTER-PACKS



TFP Fiber Optic Adapter Pack

- TFP panels are best suited for rack or cabinet mounting in Horizontal and Equipment Distribution Areas
- TFP panels are equipped with adjustable mounting brackets to provide either 19- or 23-inch rack or cabinet mounting (EIA or WECCO) as well as 4- or 5-inch recess mounting

The TFP offers a variety of standard modular adapter packs to accommodate most applications. The modular design is userfriendly and offers maximum flexibility to the end-user. CommScope's standard adapter pack offerings are multimode LC (beige), multimode LC (aqua), multimode SC duplex (beige), multimode SC duplex (aqua), singlemode LC and singlemode SC adapters with and without pigtails. (For other adapter pack offerings, see the custom configuration section).

The TFP modular adapter packs can only be used with the TFP panels. Each adapter pack contains labels that make it able to be loaded correctly in only one side of the panel. These craft friendly labels help insure correct installation. The TFP adapter packs are not interchangeable with RMG, WMG, FL1000 or FL2000 panels.

CommScope's TFP modular adapter packs are also available in additional adapter styles of 3 meter pigtails. Please note, these products are non-standard or custom configurations based on the end user's needs.

Product Classification

Regional Availability	Asia Latin America North America
Portfolio	NETCONNECT®
Product Series	TFP

General Specifications


Application	For use with TFP panels
Body Style	Left orientation Right orientation
Color, front	Black
Interface	LC/UPC SC/UPC

Dimensions

Height	33.53 mm 1.32 in
Width	176.02 mm 6.93 in

Ordering Tree

TFP-ADAPTER-PACKS

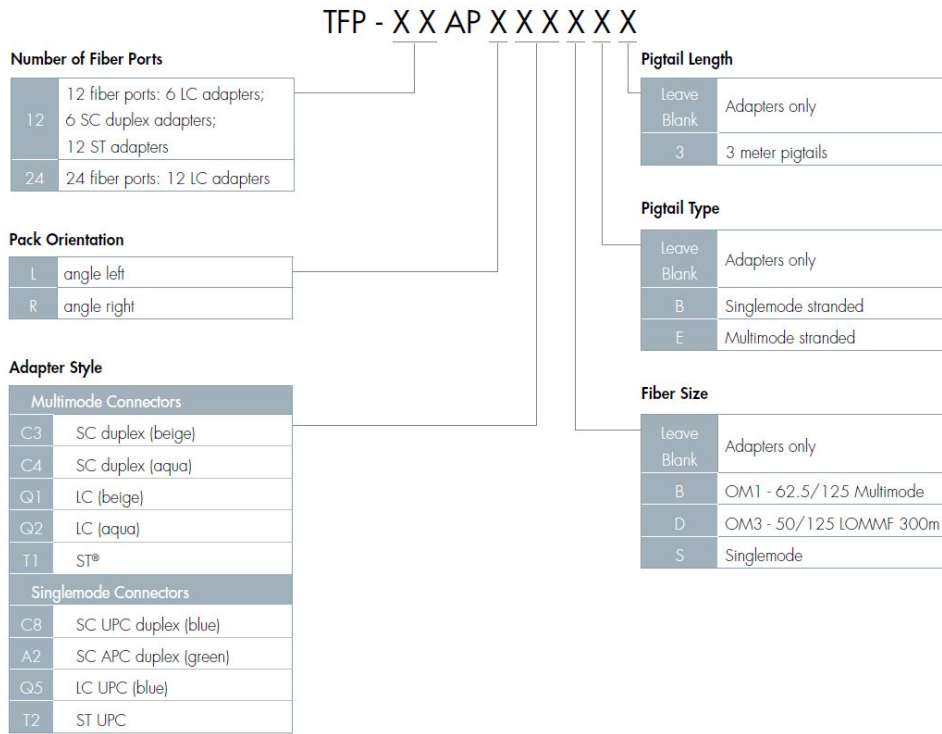

Optical Specifications

Fiber Mode Multimode | Singlemode

Environmental Specifications

Operating Temperature 0 °C to +70 °C (+32 °F to +158 °F)

Storage Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Packaging and Weights

Packaging quantity 1

Packaging Type Bag | Carton