

TTS3-34



Three-way Stand-off Adapter Kit for 3–4 in round members, includes UAAI insert

Product Classification

Product Type	Adapter
Product Brand	HELIAX®
Ordering Note	ANDREW® non-standard product

General Specifications

Adapter Type	Stand-off adapter
Mounting	3/4 in through hole Round member

Dimensions

Material Thickness	2.591 mm 0.102 in
---------------------------	---------------------

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Maximum Loading	Double stack, 1-5/8 in cable
------------------------	------------------------------

Packaging and Weights

Height, packed	12 cm 4.724 in
Width, packed	11 cm 4.331 in
Length, packed	1 cm 0.394 in
Packaging quantity	10
Weight, gross	0.58 kg 1.279 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value

TTS3-34

ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.andrew.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

31670-3	-	Round Member Adapter for 3-4 in round members
SA-38	-	Three-Way Snap-in Stand-off Adapter has two slots for round member attachment and 3/8" holes for angle adapter integration. It includes three 3/4" holes for Snap-in hangers
UAAI	-	Universal Angle Adapter Insert

31670-3



Round Member Adapter for 3–4 in round members

Product Classification

Product Type	Adapter
Ordering Note	ANDREW® standard product (Global)

General Specifications

Adapter Type	Round member adapter
---------------------	----------------------

Dimensions

Compatible Diameter, maximum	101.6 mm 4 in
Compatible Diameter, minimum	76.2 mm 3 in
Material Thickness	0.711 mm 0.028 in

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Installation Torque, maximum	6.6 ft lb 8.948 N-m
Installation Torque, minimum	4.1 ft lb 5.559 N-m
Maximum Loading	Triple stack, 1-5/8 in cable

Packaging and Weights

Height, packed	14.2 cm 5.591 in
Width, packed	14.2 cm 5.591 in
Length, packed	7.9 cm 3.11 in
Packaging quantity	10
Weight, gross	0.31 kg 0.683 lb

Regulatory Compliance/Certifications

31670-3

Agency


CHINA-ROHS
ISO 9001:2015
REACH-SVHC
ROHS
UK-ROHS

Classification

Below maximum concentration value
Designed, manufactured and/or distributed under this quality management system
Compliant as per SVHC revision on www.andrew.com/ProductCompliance
Compliant
Compliant



SA-38

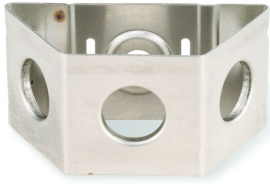

Three-Way Snap-in Stand-off Adapter has two slots for round member attachment and 3/8" holes for angle adapter integration. It includes three 3/4" holes for Snap-in hangers

Product Classification

Product Type	Adapter
Product Brand	HELIAX®
Ordering Note	ANDREW® standard product (Global)

General Specifications

Adapter Type	Stand-off adapter
Mounting	3/4 in through hole 3/8 in through hole Round member

Dimensions

Height	2.54 mm 0.1 in
Outside Width	41.402 mm 1.63 in
Outside Length	85.852 mm 3.38 in
Material Thickness	2.591 mm 0.102 in

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Maximum Loading	Double stack, 1-5/8 in cable
------------------------	------------------------------

Packaging and Weights

Height, packed	12 cm 4.724 in
Width, packed	11 cm 4.331 in
Length, packed	1 cm 0.394 in
Packaging quantity	10

SA-38

Weight, gross 0.58 kg | 1.279 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.andrew.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant





Universal Angle Adapter Insert

Product Classification

Product Type	Adapter
Product Brand	HELIAX®
Ordering Note	ANDREW® non-standard product

General Specifications

Adapter Type	Adapter
Mounting	3/8 in tapped hole

Dimensions

Outside Width	12.7 mm 0.5 in
Outside Length	25.4 mm 1 in
Material Thickness	12.7 mm 0.5 in

Material Specifications

Material Type	Stainless steel
----------------------	-----------------

Mechanical Specifications

Maximum Loading	Triple stack, 1-5/8 in cable
------------------------	------------------------------

Packaging and Weights

Height, packed	4 cm 1.575 in
Width, packed	5 cm 1.969 in
Length, packed	1 cm 0.394 in
Packaging quantity	10
Weight, gross	0.13 kg 0.287 lb

Regulatory Compliance/Certifications

UAAI

Agency

Classification

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.andrew.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

