


F-CLAMP-A2-3B

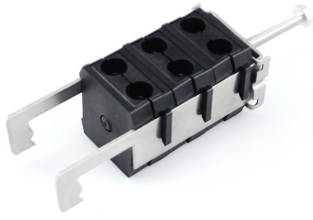

KwikClamp™ Hanger for power & fiber cables, two 4.5-9 mm holes (alongside each other), triple block; includes hardware

Product Classification

| | |
|----------------------|---|
| Product Type | Hanger kit |
| Product Brand | KwikClamp™ |
| Ordering Note | ANDREW® standard product in Europe, the Middle East, and Africa Minimum order quantity (MOQ) is 1 box |

General Specifications

| | |
|--------------------------|--|
| Cables per Hanger | 2 |
| Color | Black |
| Hanger Type | KwikClamp™ hanger |
| Mounting | 3–25 mm angle iron 3–25 mm flat plate Round Member 8-25 mm |

Dimensions

| | |
|--|-------------------|
| Maximum Stack Height | 3 |
| Height | 148 mm 5.827 in |
| Width | 44 mm 1.732 in |
| Length | 42 mm 1.654 in |
| Compatible Cable Diameter Range | 4.5–9 mm |
| Compatible Diameter, maximum | 9 mm 0.354 in |
| Compatible Diameter, minimum | 4.5 mm 0.177 in |
| Hanger Spacing, maximum | 1.83 m 6.004 ft |

Electrical Specifications

| | |
|------------------------------------|--------|
| Return Loss Effect, maximum | 0.1 dB |
| DTF Effect, maximum | 0.1 dB |

Material Specifications

| | |
|----------------------|--------------------------------------|
| Material Type | Engineered plastic Stainless steel |
|----------------------|--------------------------------------|

F-CLAMP-A2-3B

Mechanical Specifications

Vibration Survival ≥4 hours at resonant frequency

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Corrosion Resistance, minimum with no degradation ≥500 hours in salt spray chamber

Environmental Strength Capability Five times cable weight

UV Resistance, minimum with no degradation ≥124 hours exposure in accelerated UV life chamber, testing duration 1344 hrs

Packaging and Weights

Height, packed 15.5 cm | 6.102 in

Width, packed 30.5 cm | 12.008 in

Length, packed 35.5 cm | 13.976 in

Included Hardware

Packaging quantity 30

Weight, gross 6.2 kg | 13.669 lb

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|--|
| CHINA-ROHS | Below maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.andrew.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |



* Footnotes

Maximum Stack Height Fiber, Hybrid, Power