


PGP Polymer Cable Management System

Bulletin 7862015

Revision B page 1 of 2

Product Parts

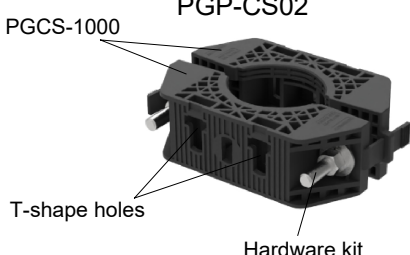

PGP-CS02

PGCS-1000

T-shape holes


Hardware kit

The clamp kit is made from two PGCS-1000 halves plus the necessary hardware kit. Can assembled on 2-3/8" or 2-7/8" pipe with an applied torque of 15 Nm.

NOTE:

1. Please use the recommended torque to install the clamp.
2. This product is compatible with both Gen 1 and Gen 2 Snap-In Hangers.


PGCS-5000

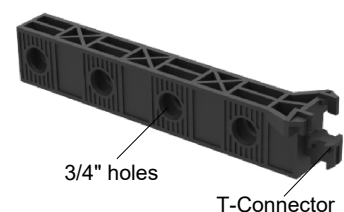

3/4" holes


T-Connector

PGCS-6000

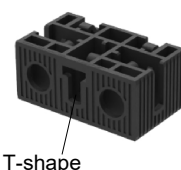

T-shape hole

PGCS-7000

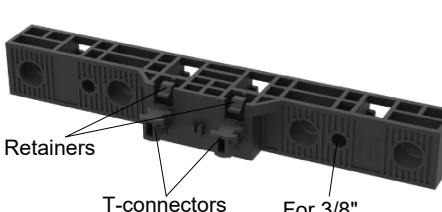


Retainers

T-connectors

For 3/8" threaded rod

PGCS-8000

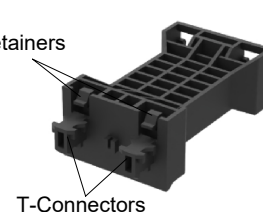


Retainers


T-Connectors

Recommended Configurations


PGP-CS04




PGP-CS08




PGP-CS10

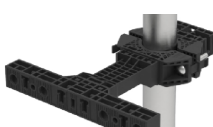


PGP-CS12




PGP-CS16




PGP-CS18

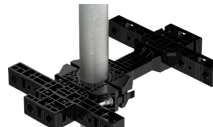


PGP-CS10-R

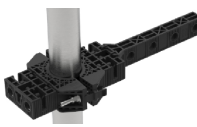


PGP-CS16L




PGP-CS18L




PGP-CS34L




PGP-CS36



PGP-CS20-R

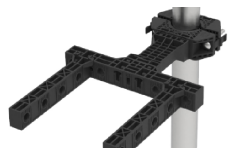

PGP-CS38-R



NOTE:

1. Intended for Jumper Cable use only.
2. Two cable hangers per 3/4" hole position, except PGP-CS20-R and PGP-CS38-R, which are limited to one cable hanger per 3/4" hole position.
3. PGP-CS12 can only be used on 2-7/8" pipes

CommScope

3642 E US Highway 70, Claremont, NC 28610 USA
 (828) 324-2200 (800) 982-1708
www.commscope.com

Customer Service 24 hours

North America: +1-800-255-1479 (toll free)
 Any country: +1-779-435-6500
 email: acicustomersupportcenter@commscope.com

Notice: CommScope disclaims any liability or responsibility for the results of improper or unsafe installation, inspection, maintenance, or removal practices.

Aviso: CommScope no acepta ninguna obligación ni responsabilidad como resultado de prácticas incorrectas o peligrosas de instalación, inspección, mantenimiento o retiro.

Avis : CommScope décline toute responsabilité pour les conséquences de procédures d'installation, d'inspection, d'entretien ou de retrait incorrectes ou dangereuses.

Hinweis: CommScope lehnt jede Haftung oder Verantwortung für Schäden ab, die aufgrund unsachgemäßer Installation, Überprüfung, Wartung oder Demontage auftreten.

Atenção: A CommScope abdica do direito de toda responsabilidade pelos resultados de práticas inadequadas e sem segurança de instalação, inspeção, manutenção ou remoção.

Avvertenza: CommScope declina eventuali responsabilità derivanti dall'esecuzione di procedure di installazione, ispezione, manutenzione e smontaggio improprie o poco sicure.

注意: CommScope 公司申明對於不恰當或不安全的安裝、檢驗、維修或拆卸操作所導致的後果不負責任 何義務和責任

© May, 2020 CommScope


PGP Polymer Cable Management System

Bulletin 7862015

Revision B page 2 of 2



Install on 2-3/8" pipe

First install the components on the both sides of the clamp (PGCS-1000), then install the two assembled clamps to the 2-3/8" pipe.

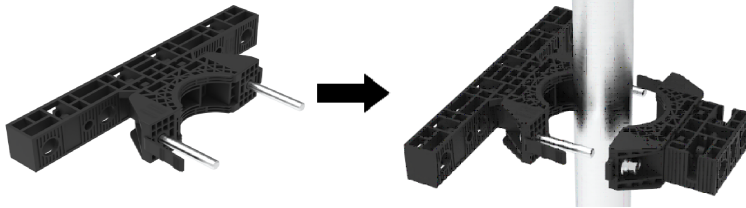

Install on 2-7/8" pipe

First use bolts to install two PGCS-1000s on the 2-7/8" pipe, and then install the required components according to the configuration.

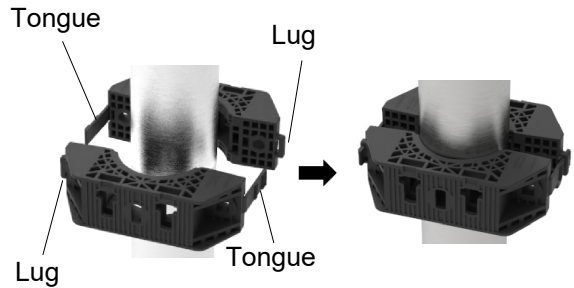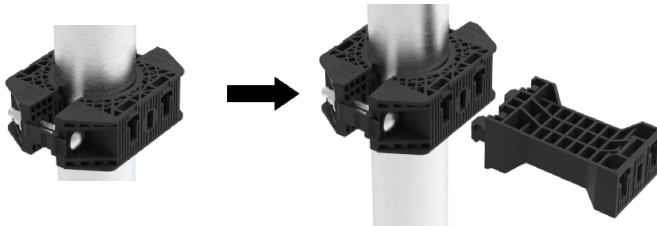

Installation of Clamp: Fix clamp to the pipe, then insert the tongues on both sides of the clamp into the corresponding lugs.

Disassembly of Clamp: Hold the tongues on both sides of the clamp. Use both hands to pull the clamp halves apart by removing the tongue from the lug.


WARNING

Do not tighten the clamp directly on the 2-3/8" pipe with bolts to prevent the clamp from deforming and making it impossible to install other components.

Installation of wedges: Fully insert the T-Connectors into the T-shape holes, slide the T-Connectors down, until you hear a "click" to indicate that the installation is complete.


Disassembly of wedges:

1

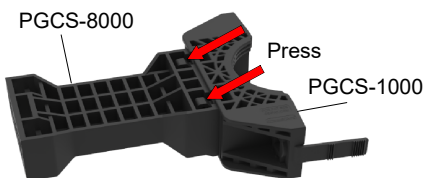


Press the arrow position with fingers to push back the retainers, until these retainers are back against the mounting surface, to allow the T-Connectors to release.

2

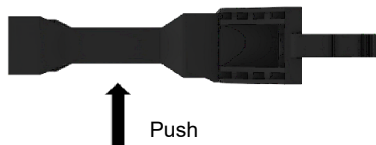

Hold the PGCS-1000, push out the PGCS-8000 as shown in the figure, and then pull it out to complete the disassembly.

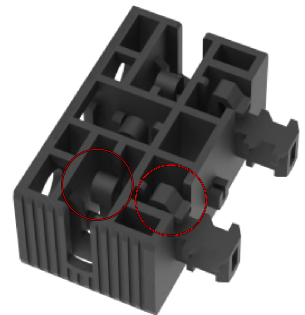

NOTE:
The same or similar retainer structure can be disassembled as shown on the left.

CommScope

3642 E US Highway 70, Claremont, NC 28610 USA
(828) 324-2200 (800) 982-1708
www.commscope.com

Customer Service 24 hours

North America: +1-800-255-1479 (toll free)
Any country: +1-779-435-6500
email: acicustomersupportcenter@commscope.com

Notice: CommScope disclaims any liability or responsibility for the results of improper or unsafe installation, inspection, maintenance, or removal practices.

Aviso: CommScope no acepta ninguna obligación ni responsabilidad como resultado de prácticas incorrectas o peligrosas de instalación, inspección, mantenimiento o retiro.

Avis : CommScope décline toute responsabilité pour les conséquences de procédures d'installation, d'inspection, d'entretien ou de retrait incorrectes ou dangereuses.

Hinweis: CommScope lehnt jede Haftung oder Verantwortung für Schäden ab, die aufgrund unsachgemäßer Installation, Überprüfung, Wartung oder Demontage auftreten.

Atenção: A CommScope abdica do direito de toda responsabilidade pelos resultados de práticas inadequadas e sem segurança de instalação, inspeção, manutenção ou remoção.

Avvertenza: CommScope declina eventuali responsabilità derivanti dall'esecuzione di procedure di installazione, ispezione, manutenzione e smontaggio improprie o poco sicure.

注意: CommScope 公司申明對於不恰當或不安全的安裝、檢驗、維修或拆卸操作所導致的後果不負責任 何義務和責任

© May, 2020 CommScope