


ULXQXQXBF

Base Product

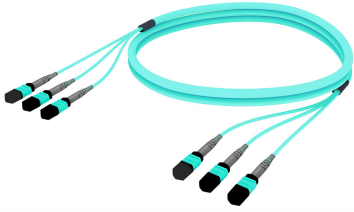

Ultra Low Loss (ULL) OM4 MPO8 (Pinned) to MPO8 (Pinned), Ruggedized fanout Cable, 24-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX ULL
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Gray
Color, connector A	Aqua
Color, boot B	Gray
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/UPC Male
Interface, Connector B	MPO-08/UPC Male
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	24

Dimensions

Cable Assembly Length Range (m)	3 – 999
--	---------

ULXQXQXBF

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree



Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Plenum

Regulatory Compliance/Certifications

ULXQXQXBF

Agency

ANATEL

ISO 9001:2015

**Classification**

Compliant

Designed, manufactured and/or distributed under this quality management system

Included Products

760161919

P-024-MP-5K-F24AQ

860633308

- Fiber indoor cable, LazrSPEED® Plenum for MPO Trunks, 24 fiber, Multimode OM4, Feet jacket marking, Aqua jacket color
- MPO8, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3m