


UGXQZQZVP

Base Product

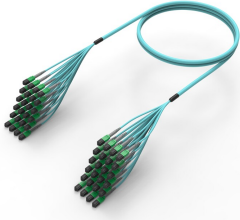

Ultra Low Loss (ULL) OM4 MPO8 APC (Pinned) to MPO8 APC (Pinned), Fiber Trunk Cable Assembly, 288-Fiber, Plenum

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber trunk cable assembly

Product Brand

Propel | SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications


Connector A, quantity	36
Color, boot A	Gray
Color, connector A	Green
Connector B, quantity	36
Color, boot B	Gray
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/APC Male
Interface, Connector B	MPO-08/APC Male
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	288

Dimensions

UGXQZQZVP

Breakout Length	23 in
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

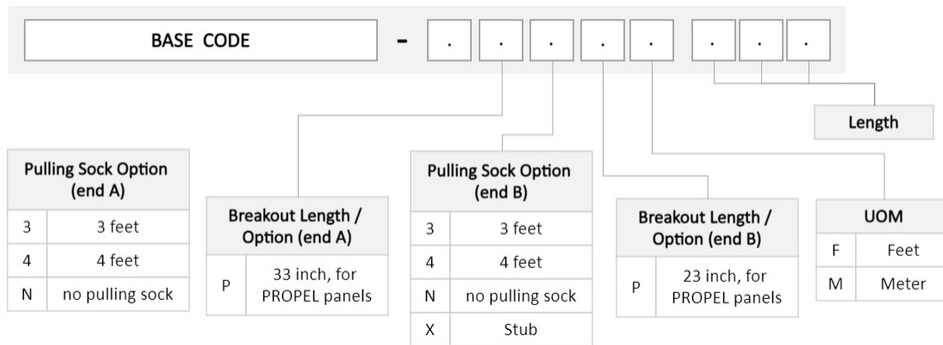

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor Plenum

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

UGXQZQZVP

- 760256584
P-288-MP-5K-F24AQ/30T
- 860663666
- Fiber indoor cable, LazrSPEED® Plenum MPO Trunk Cable, 288 fiber with 24-fiber, 3.0mm subunits, Gel-free, Multimode OM4, Feet jacket marking, Aqua jacket color
- MPO8, ULTRA LOW LOSS, MALE, Multimode, GREEN, 3mm